




Wiremold
8801S-FC2 Omnibox Series Fire Classified 1-Gang Floor Box
Part No. 8801S-FC2

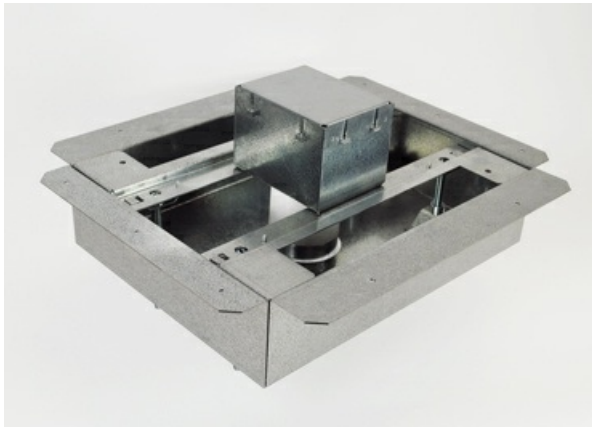

1-Gang Fire Classified Steel Floor Box. Adjustment range over deck of 2" (51mm) minimum to 6-1/2" (165mm) maximum. One 2" (51mm) conduit feed opening. Box Capacity - 53 cubic inches. This box preserves up to a 3-hour fire rating of floors in which it has been installed.

Features & Benefits

1-Gang Fire Classified Steel Floor Box. Adjustment range over deck of 2" (51mm) minimum to 6-1/2" (165mm) maximum. One 2" (51mm) conduit feed opening. Box Capacity - 53 cubic inches. This box preserves up to a 3-hour fire rating of floors in which it has been installed.

Specifications

General Info

Product Line	Wiremold	UPC Number	786776184181
Country Of Origin	United States	Construction	Assembled
Application Sector	Commercial	Standard	cULus Listed Metallic Outlet Boxes: File E2961 Guide QCIT Meets Article 314.27(C) of NEC.
Type	Floor Box		

Dimensions

Product Width US	11.375 in	Product Depth US	3.5 in
Product Length US	14.5 in	Knockout Size	2 in
Cubic Capacity	53 cu in		

Listing Agencies / 3rd Party Agencies

cULus ListingNumber	E2961	cULus Listed	Yes
---------------------	-------	--------------	-----

Buy American Act Compliance

NAFTA	Yes
-------	-----

Additional Information

RoHS Conformant	Yes
-----------------	-----

Technical Information

Cable Entry	Conduits
-------------	----------
