




adorne Collection  
adorne® 20A Dual Tamper-Resistant Outlet, Graphite  
Part No. ARTR202G4

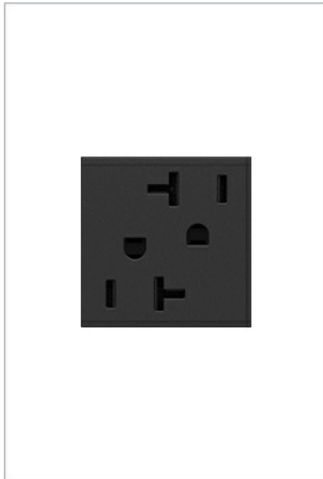

A modern upgrade for style and safety, this tamper-resistant designer outlet from the adorne Collection installs easily for the basic power every home needs, while elevating your space. Made exclusively for use with screwless Wall Plates from the adorne® Collection, sold separately.

## Features & Benefits

For complete installation, device must be paired with an adorne® screwless Wall Plate (not included). Available in a range of contemporary colors and stunning finishes.

Replaces any standard outlet with ease, in as little as 10 minutes.

Protects children with a patented tamper-resistant shutter system that prevents improper insertion of foreign objects, complete with "invisible shutters" for an invisible effect.

More color options available to fit any style, including finishes to match current hardware and lighting trends.

## Specifications

### General Info

Product Line	Pass & Seymour	Replaced by Part Number	
Color	Graphite	Country Of Origin	China
Number of Receptacles	2	Outlet Type	Indoor, Residential, Tamper-Resistant
Warranty Type	Limited Lifetime Warranty	Type	Outlet

### Dimensions

Product Width US	1.77 in	Product Depth US	1.73 in
Product Height US	2.12 in		

### Technical Information

Connection	Side and Back Wire	Number of Gangs	1
------------	--------------------	-----------------	---

---

Amperage	20 A	Number of Poles	Double Pole
Indoor/Outdoor	Indoor	NEMA Configuration Code	5-20R
Mounting Type	Box	Voltage	125.0 V
Connection Type	Internal Pressure Plates	Environmental Conditions	95% (relative humidity, non-condensing)

---