




adorne Collection  
adorne® 15A Tamper-Resistant Ultra-Fast USB Type-A/C Outlet, Graphite  
Part No. ARTRUSB156ACG4

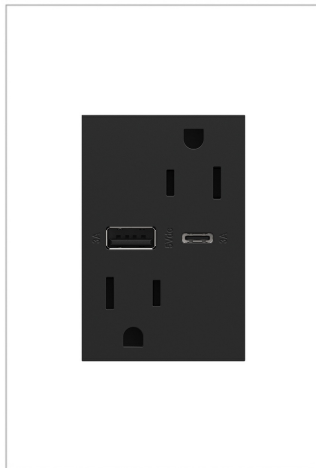

Charge phones, tablets and more up to 40% faster, with Ultra-Fast USB Outlets from the adorne® Collection. Made to deliver a leading 6 amps of power, it features two built-in USB connections, including one to fit USB Type-C devices, and provides a fast, future-proof solution for convenient in-wall charging without an adapter. Easily replacing traditional outlets in as little as ten minutes, this Ultra-Fast USB Outlet transforms your space with modern functionality and the unique, contemporary aesthetic of adorne. Made exclusively for use with screwless Wall Plates from the adorne® Collection, sold separately.

## Features & Benefits

For complete installation, device must be paired with an adorne® screwless Wall Plate (not included). Available in a range of contemporary colors and stunning finishes.

Features an industry-leading 6.0A of power, as well as Smart Chip technology, to maximize charging speed for each USB connection.

Protects children with a patented tamper-resistant shutter system that prevents improper insertion of foreign objects, complete with "invisible shutters" for an invisible effect.

Legrand USB Outlets are manufactured through high-quality design, sourcing and production, and backed by a Lifetime Warranty.

Provides fast and convenient built-in charging, without sacrificing plugs or requiring a bulky adapter.

Includes connections for both traditional USB Type-A and the newer USB Type-C, to accommodate all mobile devices.

Replaces a traditional outlet easily, in as little as 10 minutes. Offers greater plug capacity to accommodate larger products.

More color options available to fit any style, including finishes to match current hardware and lighting trends.

## Specifications

### General Info

Product Line	Pass & Seymour	Replaced by Part Number	
Color	Graphite	Country Of Origin	China
Number of Receptacles	2	Features	USB-A Charging, USB-C Charging
Outlet Type	Indoor, Residential, Tamper-Resistant, USB-Charging	Application Sector	Residential/Commercial
Standard	yes	Warranty Type	Limited Lifetime Warranty

---

Type	Outlet
------	--------

---

## Dimensions

---

Product Width US	2.5 in	Product Depth US	1.77 in
------------------	--------	------------------	---------

---

Product Height US	3.0 in
-------------------	--------

---

## Technical Information

---

Is Tamper-Resistant	Yes	USB Amperage	6 A
---------------------	-----	--------------	-----

---

Connection	USB Type A/C	Number of USBs	2
------------	--------------	----------------	---

---

Number of Gangs	1	USB Power Output	15 W
-----------------	---	------------------	------

---

Amperage	15 A	Number of Poles	Double Pole
----------	------	-----------------	-------------

---

Indoor/Outdoor	Indoor	NEMA Configuration Code	5-15R
----------------	--------	-------------------------	-------

---

Mounting Type	Box	Voltage	125.0 V
---------------	-----	---------	---------

---

Connection Type	Internal Pressure Plates	Environmental Conditions	95% (relative humidity, non-condensing)
-----------------	--------------------------	--------------------------	---

---