




On-Q
42-inch Enclosure with Screw-On Cover
Part No. EN4200

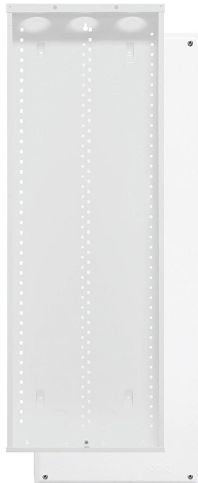

Perfect for larger installations, this 42" enclosure features universal On-Q style mounting holes that are compatible with all bay-style modules. It also includes larger top openings that make pulling wire easier as well as additional knockouts, more s

Features & Benefits

42-in Enclosure with Screw-On Cover

Drywall depth indicators

Flush and surface installation

Mounting tabs provide correct flush-mount position for standard installations

Patented mounting system offers versatile module mounting options

Literature pouch included for dealer information

Includes self-adhesive cable identification table

Cover included

Made in the USA

Specifications

General Info

Product Line	On-Q	Color	White
UPC Number	804428023166	Country Of Origin	United States
Package Quantity	1	Application Sector	Residential
Standard	UL (UL985, UL1023, UL1863), cULus, CSA, RoHS	Type	Enclosure

Dimensions

Product Width US	14.25 in	Product Depth US	3.6 in
Product Height US	42.0 in		

Listing Agencies / 3rd Party Agencies

CSA Listed	Yes	cULus Listed	Yes
------------	-----	--------------	-----

Additional Information

RoHS Conformant	Yes	Product Environmental Profile	Yes
-----------------	-----	-------------------------------	-----

Technical Information

Thickness	0.1 in	Enclosure Type	Traditional
-----------	--------	----------------	-------------

Cable Entry	(2) rectangular knockouts for 1-gang electrical box,(6) rear knockouts,(3) top knockouts	Frame	Cold Rolled Steel
-------------	--	-------	-------------------
