




radiant Collection
radiant® Fan Speed Control De-Hummer, Single Pole/3-Way, Tri-Color
Part No. HDH163PMMTC

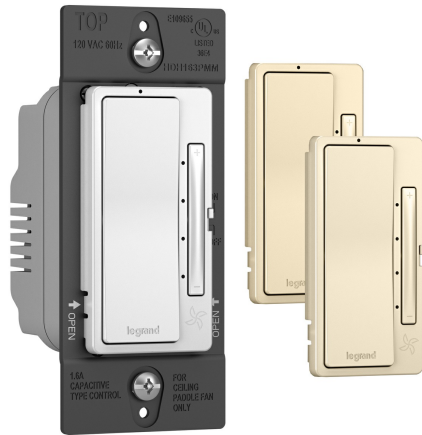

Specially designed capacitive circuitry de-hummer feature virtually eliminates fan motor hum for quiet fan speed control. Made exclusively for use with screwless Wall Plates from the radiant® Collection, sold separately.

Features & Benefits

Multi-location dimming compatible with 3-way wiring for simple installation.

Designed to virtually eliminate the motor's hum for quieter use.

Constant memory returns lights to previous level after a power failure.

Part of the radiant® collection.

Complete the look with a sleek, screwless radiant® Wall Plate, and coordinate with other designer switches and outlets available from the radiant® Collection.

Specifications

General Info

Product Line	Pass & Seymour	Color	White
Country Of Origin	China	Features	Fan Control, Indicator Lights
Switch Type	Paddle	Number of Switches	1
Warranty Type	1-Year Limited Warranty		

Dimensions

Product Width US	1.75 in	Product Depth US	1.25 in
Product Height US	4.25 in		

Listing Agencies / 3rd Party Agencies

cULus Listed	Yes
--------------	-----

Technical Information

Number of Gangs	1	Amperage	15 A
-----------------	---	----------	------

Number of Poles	3-Way, Single Pole	Mounting Type	Box
-----------------	--------------------	---------------	-----

Voltage	120.0 V
---------	---------
