




On-Q
12-inch Enclosure with Screw-On Cover
Part No. EN1200

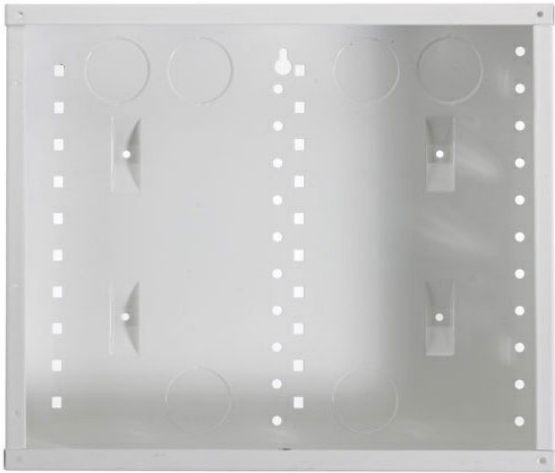

This 12-inch enclosure is the perfect solution for a basic or entry-level structured wiring system. It features large top openings that make pulling wire easier than ever before. The enclosure also boasts multiple knockouts, side lances, and side tabs

Features & Benefits

12-in Enclosure with Screw-On Cover

Drywall depth indicators

Flush and surface installation

Mounting tabs provide correct flush-mount position for standard installations

Patented mounting system offers versatile module mounting options

Literature pouch included for dealer information

Includes self-adhesive cable identification table

Cover included

Made in the USA :

Specifications

General Info

Product Line	On-Q	Color	White
UPC Number	804428050650	Country Of Origin	United States
Package Quantity	1	Application Sector	Residential
Standard	UL (UL985, UL1023, UL1863), cULus, CSA, RoHS	Type	Enclosure

Dimensions

Product Width US	14.25 in	Product Depth US	3.6 in
Product Height US	12.13 in		

Listing Agencies / 3rd Party Agencies

CSA Listed	Yes	cULus Listed	Yes
------------	-----	--------------	-----

Additional Information

RoHS Conformant	Yes
-----------------	-----

Technical Information

Thickness	0.1 in	Enclosure Type	Traditional
Cable Entry	(3) top knockouts,(6) rear knockouts,(2) rectangular knockouts for 1-gang electrical box	Frame	Cold Rolled Steel
