




radiant Collection  
radiant® 20A 125V Tamper-Resistant Outlet, Light Almond  
Part No. 885TR20SLA

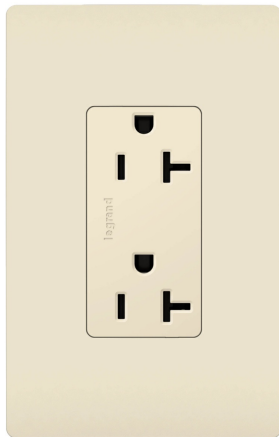

Take a step up from standard with Legrand's 20A/125V radiant® Tamper Resistant, Self-Grounding, Duplex Outlet. This tamper-resistant duplex 20-amp outlet installs easily for the basic power every home needs, while elevating your space with the sleek, clean lines of radiant® for a sophisticated look. To help prevent improper insertion of foreign objects and comply with NEC Article 406.12, these receptacles feature black "invisi-shutters" that disappear for an invisible effect preferred by end users. This outlet also includes a self-grounding feature that makes it ideal for residential and multi-dwelling applications. Pair with a screwless radiant® Wall Plate and other designer switches and outlets from the radiant® Collection for a cohesive design throughout the home. Made exclusively for use with screwless Wall Plates from the radiant® Collection, sold separately.

## Features & Benefits

Ideal for Residential Applications & Multi-Dwelling units where 20A devices are required

Meets National Electric Code Tamper-Resistant requirements per Article 406.12

Black "Invisi-Shutters" disappear for an invisible effect

Side Wire Only accepts #12-#14 AWG

Auto-Ground Clip assures a positive ground connection is made

Pair with a screwless radiant wall plate and coordinate with other designer switches & outlets from the collection for a cohesive look.

## Specifications

### General Info

Product Line	Pass & Seymour	Replaced by Part Number	
Color	Light Almond	Finish	Glossy
Country Of Origin	China	Receptacle Type	Straight Blade
Number of Receptacles	2	Construction	Injection molded plastic
Features	Self-Grounding	Outlet Type	Indoor, Self-Grounding, Tamper-Resistant
Package Quantity	1	Application Sector	Residential

Standard	RoHS, UL (UL498, E140596), cULus (E140596), CSA (C22.2 No. 42), NEMA (WD-1 & WD-6)	Warranty Type	1-Year Limited Warranty
Type	Decorator, Duplex, Outlet		
<b>Dimensions</b>			
Product Width US	1.42 in	Product Weight US	0.122 lb
Product Depth US	1.03 in	Product Height US	4.2 in
<b>Listing Agencies / 3rd Party Agencies</b>			
CSA Listed	Yes	cULus ListingNumber	885TR20SLA
cULus Listed	Yes	CSA File Number	C22.2 No. 42
<b>Additional Information</b>			
RoHS Conformant	Yes		
<b>Technical Information</b>			
Is Tamper-Resistant	Yes	Connection	Side Wire Only
Number of Wires	3	Amperage	20 A
Number of Poles	Double Pole	Wire Size	14 - 12 AWG
Is Weather Resistant	No	Indoor/Outdoor	Indoor
NEMA Configuration Code	5-20R	Mounting Type	Screwless
Voltage	125.0 V	Environmental Conditions	98% (relative humidity, non-condensing)