




Cablofil
Vtrough Center Hanger 100 BLACK
Part No. 960765

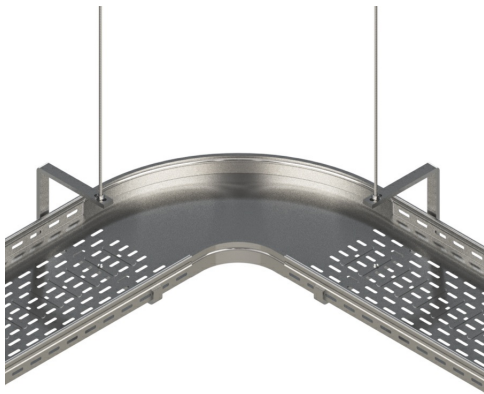

Center Hanging Fiber Trough tray makes adding cables easy with the new ESO P31. The open side allows greater access to cable pathways up to 12" wide and makes covers easier to remove and replace. Designed for medium duty loads, the ESO P31 accepts 3/8" threaded rod and attaches to the tray with EZBN1/4 bolts. ESO P31 available in EZ (Electrozinc) and GC (Hot Dipped Galvanized) to match your application environment.

Features & Benefits

Open side allows cables to added to pathway easily
Use with 3/8" threaded rod
Packaged in sets of 6 and 10

Works with Fiber Trough or V-Trough Tray up to 12" wide
Steel construction is available in two finishes.

Specifications

General Info

| | | | |
|--------------|--------------|-------------------|----------------|
| Product Line | Cablofil | Finish | Custom Painted |
| UPC Number | 800388471825 | Country Of Origin | Italy |

Dimensions

| | | | |
|-------------------|-------------|-------------------|---------|
| Product Width US | 4.25 in | Product Weight US | 0.75 lb |
| Product Volume US | 0.015 cu ft | Product Depth US | 6.25 in |
| Product Height US | 1.0 in | | |

Buy American Act Compliance

| | |
|-----|-----|
| BAA | Yes |
|-----|-----|