




Cablofil
20W Fast Trapeze Bracket High-Resistance Finish
Part No. EWS_CB_14506

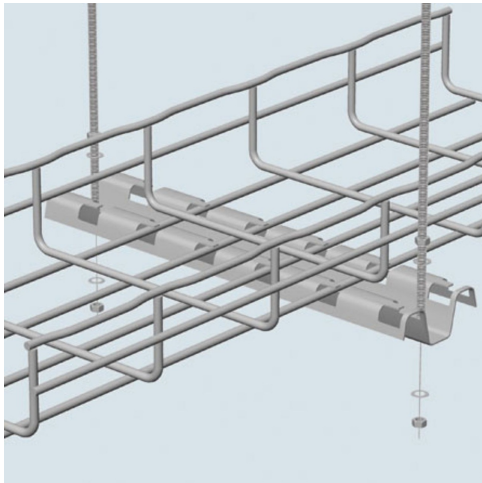

Designed to take the place of traditional strut in a trapeze application. Our FAS Profile system attaches to tray with no nuts or bolts. It is a safer, faster option to install suspended wire mesh cable tray. Can be cut to the length required for installation.

Features & Benefits

Patented FAS style attachment secures tray without nuts and bolts

For trapeze hung installations, use 4" longer profile than tray width

Maximum threaded rod size is 3/8". For use with larger sizes of threaded rod, bracket holes must be drilled larger.

Threaded rods, nuts and washers sold separately

120W Fast Trapeze Bracket can be cut to the length required for installation.

Specifications

General Info

Product Line	Cablofil	Finish	High Resistance
UPC Number	800388545557	Country Of Origin	China
Application Sector	Commercial, Industrial	Type	Supports

Dimensions

Product Width US	2.7 in	Product Weight US	1.3 lb
Product Depth US	19.5 in	Product Height US	1.4 in
Product Length US	19.5 in		

Additional Information

RoHS Compliant

Yes
