




**Cablofil**  
**28W Fast Trapeze Bracket High-Resistance Finish**  
Part No. EWS\_CB\_14706

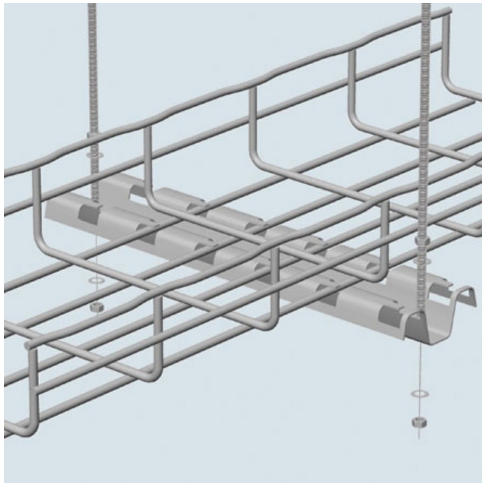

Designed to take the place of traditional strut in a trapeze application. Our FAS Profile system attaches to tray with no nuts or bolts. It is a safer, faster option to install suspended wire mesh cable tray. Can be cut to the length required for installation.

## Features & Benefits

Patented FAS style attachment secures tray without nuts and bolts

For trapeze hung installations, use 4" longer profile than tray width

Maximum threaded rod size is 3/8". For use with larger sizes of threaded rod, bracket holes must be drilled larger.

Threaded rods, nuts and washers sold separately

120W Fast Trapeze Bracket can be cut to the length required for installation.

## Specifications

### General Info

Product Line	Cablofil	Finish	High Resistance
UPC Number	800388545588	Country Of Origin	China
Application Sector	Commercial, Industrial	Type	Supports

### Dimensions

Product Width US	2.7 in	Product Depth US	27.3 in
Product Height US	1.4 in	Product Length US	27.3 in

### Additional Information

RoHS Compliant	Yes
----------------	-----