




On-Q  
12-inch Enclosure with Screw-On Cover  
Part No. EN1200

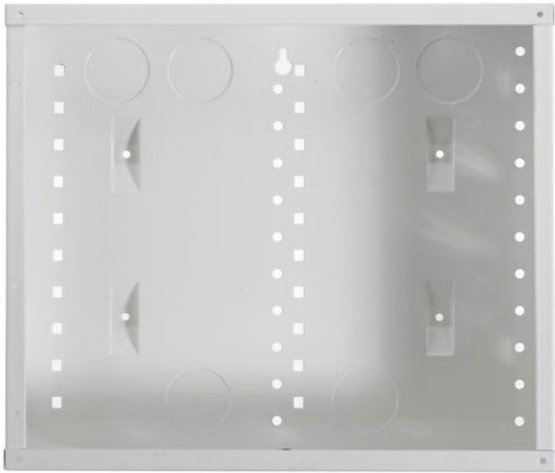

This 12-inch enclosure is the perfect solution for a basic or entry-level structured wiring system. It features large top openings that make pulling wire easier than ever before. The enclosure also boasts multiple knockouts, side lances, and side tabs

## Features & Benefits

12-in Enclosure with Screw-On Cover	Drywall depth indicators
Flush and surface installation	Mounting tabs provide correct flush-mount position for standard installations
Patented mounting system offers versatile module mounting options	Literature pouch included for dealer information
Includes self-adhesive cable identification table	Cover included
Made in the USA :	

## Specifications

### General Info

Product Line	On-Q	Color	White
UPC Number	804428050650	Country Of Origin	United States
Package Quantity	1	Application Sector	Residential
Standard	UL (UL985, UL1023, UL1863), cULus, CSA, RoHS	Type	Enclosure

### Dimensions

Product Width US	14.25 in	Product Depth US	3.6 in
Product Height US	12.13 in		

Listing Agencies / 3rd Party Agencies

CSA Listed	Yes	cULus Listed	Yes
------------	-----	--------------	-----

Additional Information

RoHS Conformant	Yes
-----------------	-----

Technical Information

Thickness	0.1 in	Enclosure Type	Traditional
Cable Entry	(6) rear knockouts, (3) top knockouts, (2) rectangular knockouts for 1-gang electrical box	Frame	Cold Rolled Steel