




Pass and Seymour
20A Audible Alarm Sensitive Appliance GFCI Receptacle, White
Part No. 2097TRAAPLW

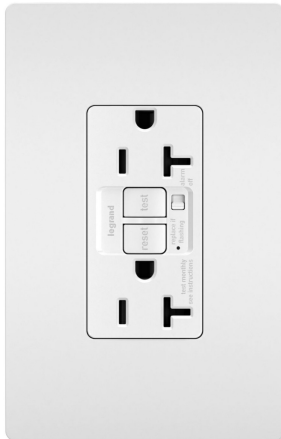

Audible alarm (rated at 60db at 10 feet) alert of a tripped condition is ideal when the GFCI is subject to an obstructed view or otherwise cannot be easily seen. In addition, as sensitive appliances that are increasingly including variable speed drives to deliver energy-saving operation lead to more cases of unwanted tripping of connected GFCIs, the 20A Audible Alarm Sensitive Appliance GFCI can reduce the incidence of nuisance tripping, saving installers unpaid callbacks.

Features & Benefits

Sensitive Appliance GFCI receptacles can reduce installer's unpaid callbacks by reducing incidence of nuisance tripping that can be caused by variable speed drives in newer appliances.

Audible alarm (rated at 60db at 10 feet) alert of a tripped condition is ideal when the GFCI is subject to an obstructed view or otherwise cannot be easily seen.

Protects against electrical shock caused by ground-fault occurrences. Unlike breaker alternatives, GFCI receptacles allow one to easily conduct test and reset to ensure safety right on the face of the device.

Specifications

General Info

Product Line	Pass & Seymour	Color	White
Finish	Matte	UPC Number	785007449655
Country Of Origin	China	Number of Receptacles	2
Features	Audible Alarm	Outlet Type	GFCI, Self-Test, Tamper-Resistant
Application Sector	Residential/Commercial	Standard	FEDSPEC
Warranty Type	1-Year Limited Warranty	Type	GFCI, Tamper-Resistant

Dimensions

Product Width US	1.73 in	Product Depth US	1.03 in
------------------	---------	------------------	---------

Product Height US 4.2 in

Listing Agencies / 3rd Party Agencies

cULus Listed Yes

Additional Information

RoHS Compliant Yes

Technical Information

Seismic Tested No Is Tamper-Resistant Yes

Number of Gangs 1 Amperage 20 A

Number of Poles Double Pole Is Weather Resistant No

Indoor/Outdoor Indoor Wattage 2500 W

Mounting Type Box
