




Wiremold
Plug-In Outlet Center Unit / 120V/15A/72 long/24 O/L /lighted switch/6' cord
Part No. UL2065BC

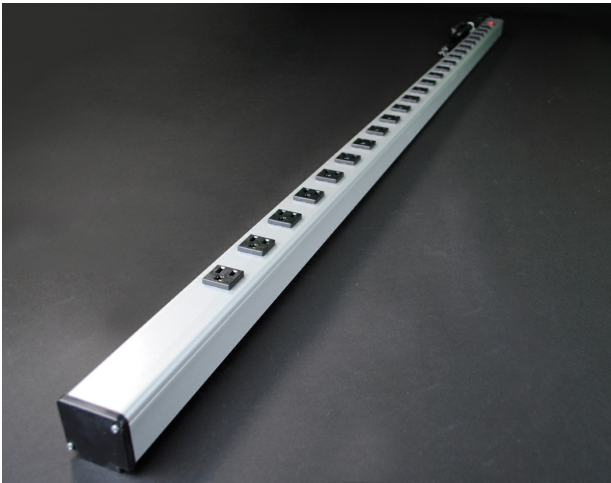

Twenty-four outlets, rugged gray aluminum housing, 15A, lighted switch, 6' (1.8m) 14/3 SJT black cord with NEMA5-15 plug. Length 72" (1.8m). Receptacle center-to-center 2 1/2" (64mm). Snap-on, slide-off mounting.

Features & Benefits

Twenty-four outlets, rugged gray aluminum housing, 15A, lighted switch, 6' (1.8m) 14/3 SJT black cord with NEMA5-15 plug. Length 72" (1.8m). Receptacle center-to-center 2 1/2" (64mm). Snap-on, slide-off mounting.

Specifications

General Info

Product Line	Wiremold	UPC Number	786776047738
Country Of Origin	Mexico	Receptacle Type	Simplex
Number of Receptacles	24	Application Sector	Commercial
Standard	cULus Recognized: File E66421 Guide XBYS XUHT VZCA	Type	PIOC

Dimensions

Product Width US	2.0 in	Product Length US	72.0 in
------------------	--------	-------------------	---------

Listing Agencies / 3rd Party Agencies

cULus ListingNumber	E66421	cULus Listed	Yes
---------------------	--------	--------------	-----

Buy American Act Compliance

NAFTA	Yes
-------	-----

Additional Information

RoHS Conformant	Yes
-----------------	-----

Technical Information

Phase	Single	Frequency Rating	60 Hz
-------	--------	------------------	-------

Amperage	15 A	Enclosure Type	Aluminum
----------	------	----------------	----------

Mounting Type	Slide-off, Snap-on	Voltage	125.0 V
---------------	--------------------	---------	---------

Environmental Conditions	Dry interior locations
--------------------------	------------------------
