




Wattstopper
Wattstopper PLUS Wireless Scene Dimming Wallstation, 3 Button, Gray
Part No. BCS_WA_EN-WS-SC3-ZB-GR

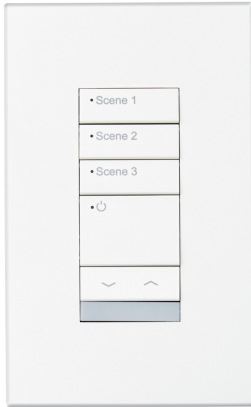

The SC Scene Dimming Wallstation series is a multi-scene, single-zone dimming Wallstation that provides customized light level control in areas such as boardrooms, conference rooms, private offices, and other areas requiring architectural dimming. The SC Series allows the user to select pre-programmed light levels or "scenes" with the push of a button. Scene configuration can be changed via Software.

Features & Benefits

The sleek, aesthetic designs are suitable for all interior locations

Setup and monitoring via Polaris software with easy mapping/re-mapping

10-year battery life for wireless version with automatic battery monitoring via Polaris software

Specifications

General Info

Product Line	Wattstopper	Color	Gray
Finish	Plastic	UPC Number	840356702032
Country Of Origin	Canada	Switch Type	Push
Number of Switches	4	Application Sector	Commercial
Warranty Type	5-Year	Type	Switch

Dimensions

Product Width US	2.76 in	Product Weight US	0.35 lb
Product Depth US	0.94 in	Product Height US	4.5 in

Listing Agencies / 3rd Party Agencies

CE Certified	Yes	FCC Compliant	Yes
--------------	-----	---------------	-----

cUL Listed	Yes
------------	-----

Additional Information

RoHS Compliant	Yes	Product Has Potential to Contribute to LEED	Yes
----------------	-----	---	-----

Technical Information

Operating Temperature Min	-10 °C	Has Battery	Yes
---------------------------	--------	-------------	-----

Battery Capacity	3 V	Frequency Band	2.4 GHz
------------------	-----	----------------	---------

Operating Temperature Max	40 °C	Number of Buttons	3
---------------------------	-------	-------------------	---

Number of Rockers	1	Wireless Range	Zigbee, up to 100 ft
-------------------	---	----------------	----------------------

Input Voltage	3 VDC	Indoor/Outdoor	Indoor
---------------	-------	----------------	--------

Battery Life	Up to 10 Years	Mounting Type	Surface
--------------	----------------	---------------	---------

Battery	2 AA	Operating Temperature	-10°-40°C
---------	------	-----------------------	-----------

Operating Humidity	5-95% RH (Non-Condensing)	Wire Connection Type	Wireless
--------------------	---------------------------	----------------------	----------

Antenna Pattern	Omni-directional	Engraving Type	Icon with Text
-----------------	------------------	----------------	----------------
