




Wattstopper
Wattstopper PLUS Wireless Scene Dimming Wallstation, 5 Button, Gray
Part No. BCS_WA_EN-WS-SC5-ZB-GR

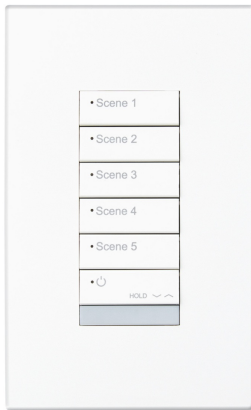

The SC Scene Dimming Wallstation series is a multi-scene, single-zone dimming Wallstation that provides customized light level control in areas such as boardrooms, conference rooms, private offices, and other areas requiring architectural dimming. The SC Series allows the user to select pre-programmed light levels or "scenes" with the push of a button. Scene configuration can be changed via Software.

Features & Benefits

The sleek, aesthetic designs are suitable for all interior locations

Setup and monitoring via Polaris software with easy mapping/re-mapping

10-year battery life for wireless version with automatic battery monitoring via Polaris software

Specifications

General Info

| | | | |
|--------------------|-------------|--------------------|--------------|
| Product Line | Wattstopper | Color | Gray |
| Finish | Plastic | UPC Number | 840356702124 |
| Country Of Origin | Canada | Switch Type | Push |
| Number of Switches | 6 | Application Sector | Commercial |
| Warranty Type | 5-Year | Type | Switch |

Dimensions

| | | | |
|------------------|---------|-------------------|---------|
| Product Width US | 2.76 in | Product Weight US | 0.35 lb |
| Product Depth US | 0.94 in | Product Height US | 4.5 in |

Listing Agencies / 3rd Party Agencies

| | | | |
|--------------|-----|---------------|-----|
| CE Certified | Yes | FCC Compliant | Yes |
|--------------|-----|---------------|-----|

| | |
|------------|-----|
| cUL Listed | Yes |
|------------|-----|

Additional Information

| | | | |
|----------------|-----|---|-----|
| RoHS Compliant | Yes | Product Has Potential to Contribute to LEED | Yes |
|----------------|-----|---|-----|

Technical Information

| | | | |
|---------------------------|--------|-------------|-----|
| Operating Temperature Min | -10 °C | Has Battery | Yes |
|---------------------------|--------|-------------|-----|

| | | | |
|------------------|-----|----------------|---------|
| Battery Capacity | 3 V | Frequency Band | 2.4 GHz |
|------------------|-----|----------------|---------|

| | | | |
|---------------------------|-------|-------------------|---|
| Operating Temperature Max | 40 °C | Number of Buttons | 5 |
|---------------------------|-------|-------------------|---|

| | | | |
|-------------------|---|----------------|----------------------|
| Number of Rockers | 1 | Wireless Range | Zigbee, up to 100 ft |
|-------------------|---|----------------|----------------------|

| | | | |
|---------------|-------|----------------|--------|
| Input Voltage | 3 VDC | Indoor/Outdoor | Indoor |
|---------------|-------|----------------|--------|

| | | | |
|--------------|----------------|---------------|---------|
| Battery Life | Up to 10 Years | Mounting Type | Surface |
|--------------|----------------|---------------|---------|

| | | | |
|---------|------|-----------------------|-----------|
| Battery | 2 AA | Operating Temperature | -10°-40°C |
|---------|------|-----------------------|-----------|

| | | | |
|--------------------|---------------------------|----------------------|----------|
| Operating Humidity | 5-95% RH (Non-Condensing) | Wire Connection Type | Wireless |
|--------------------|---------------------------|----------------------|----------|

| | | | |
|-----------------|------------------|----------------|----------------|
| Antenna Pattern | Omni-directional | Engraving Type | Icon with Text |
|-----------------|------------------|----------------|----------------|
